




NEW

**Thin Section | Four-Point Contact
BALL BEARINGS**

- 52100 Chrome Steel
- Four-Point Contact Bearings
- Snap-Over Cage
- ABEC 1

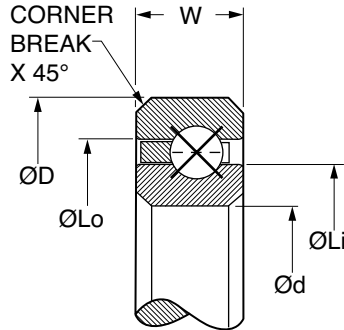

Catalog Number	d Bore	D O.D.	Pitch	W Weight	Ball Complement		Internal Clearance	
					Ball Qty.	Ball Dia.	Min.	Max.
BBXFOR-KC042XPO	4.246	4.996	4.6212	.3750	37	3/16	.0016	.0026
BBXFOR-KD042XPO		5.246	4.7460	.5000	28	1/4		
BBXFOR-KF042XPO	4.246	5.746	4.9960	.7500	20	3/8	.0016	.0026
BBXFOR-KG042XPO		6.246	5.2460	1.0000	15	1/2		
BBXFOR-KA045XPO	4.500	5.000	4.7500	.2500	57	1/8	.0016	.0026
BBXFOR-KB045XPO		5.125	4.8125	.3125	48	5/32		
BBXFOR-KC045XPO	4.500	5.250	4.8750	.3750	39	3/16	.0016	.0026
BBXFOR-KD045XPO		5.500	5.0000	.5000	30	1/4		
BBXFOR-KF045XPO	4.500	6.000	5.2500	.7500	21	3/8	.0016	.0026
BBXFOR-KG045XPO		6.500	5.5000	1.0000	16	1/2		

Catalog Number	Lo Outer Race I.D.	Li Inner Race O.D.	Corner Break	Weight lbs.	Max. Radial rpm	Max. Axial rpm	Load Rating	
							Radial lbs.	Axial lbs.
BBXFOR-KC042XPO	4.716	4.527	.05	.47	825	2350	900	2270
BBXFOR-KD042XPO	4.872	4.620	.07	.83	950	2525	1400	3500
BBXFOR-KF042XPO	5.185	4.808	.09	2.00	925	2550	2700	6700
BBXFOR-KG042XPO	5.497	4.995		3.80		2500	4450	11350
BBXFOR-KA045XPO	4.813	4.687	.03	.23	780	2230	525	1310
BBXFOR-KB045XPO	4.891	4.734	.05	.33	800	2300	740	1820
BBXFOR-KC045XPO	4.970	4.780	.05	.48	780	2230	910	2310
BBXFOR-KD045XPO	5.126	4.874	.07	.88	890	2420	1450	3600
BBXFOR-KF045XPO	5.438	5.062	.09	2.10	875	2400	2800	6850
BBXFOR-KG045XPO	5.751	5.249		4.00	850		4550	11550

NOTE: Larger sizes available upon request. Stainless Steel available upon special request.
Minimum buy quantities may apply.