


# NEW

## Axial THRUST WASHERS

• Steel

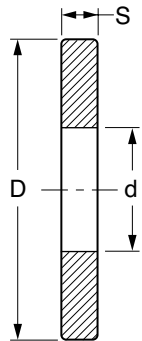

Catalog Number	d Bore	D Outside Dia.	S Width	Maximum Speed (rpm)	Weight g	Matching Bearing Designation
				Oil		
BTHBNGMAS0414	4	14	1	18000	1	BTHBNGMAXK0414TN
BTHBNGMAS0515	5	15		17000	1	BTHBNGMAXK0515TN
BTHBNGMAS0619	6	19		16000	2	BTHBNGMAXK0619TN
BTHBNGMAS0821	8	21	1	15000	2	BTHBNGMAXK0821TN
BTHBNGMAS1024	10	24		14000	3	BTHBNGMAXK1024
BTHBNGMAS1226	12	26		16000	3	BTHBNGMAXK1226
BTHBNGMAS1528	15	28	1	11000	3	BTHBNGMAXK1528
BTHBNGMAS1730	17	30		10000	4	BTHBNGMAXK1730
BTHBNGMAS2035	20	35		8500	5	BTHBNGMAXK2035
BTHBNGMAS2542	25	42	1	7000	7	BTHBNGMAXK2542
BTHBNGMAS3047	30	47		6000	8	BTHBNGMAXK3047
BTHBNGMAS3552	35	52		5500	9	BTHBNGMAXK3552
BTHBNGMAS4060	40	60	1	4700	12	BTHBNGMAXK4060
BTHBNGMAS4565	45	65		4300	13	BTHBNGMAXK4565
BTHBNGMAS5070	50	70		3900	14	BTHBNGMAXK5070
BTHBNGMAS5578	55	78	1	3500	18	BTHBNGMAXK5578
BTHBNGMAS6085	60	85		3200	22	BTHBNGMAXK6085
BTHBNGMAS6590	65	90		3000	24	BTHBNGMAXK6590
BTHBNGMAS7095	70	95	1	2900	25	BTHBNGMAXK7095
BTHBNGMAS75100	75	100		2700	27	BTHBNGMAXK75100
BTHBNGMAS80105	80	105		2600	28	BTHBNGMAXK80105
BTHBNGMAS85110	85	110	1	2400	29	BTHBNGMAXK85110
BTHBNGMAS90120	90	120		2300	39	BTHBNGMAXK90120
BTHBNGMAS100135	100	135		2000	50	BTHBNGMAXK100135
BTHBNGMAS110145	110	145	1	1900	55	BTHBNGMAXK110145
BTHBNGMAS120155	120	155		1700	59	BTHBNGMAXK120155
BTHBNGMAS130170	130	170		1600	65	BTHBNGMAXK130170
BTHBNGMAS140180	140	180	1	1500	79	BTHBNGMAXK140180
BTHBNGMAS150190	150	190		1400	84	BTHBNGMAXK150190
BTHBNGMAS160200	160	200		1300	89	BTHBNGMAXK160200