



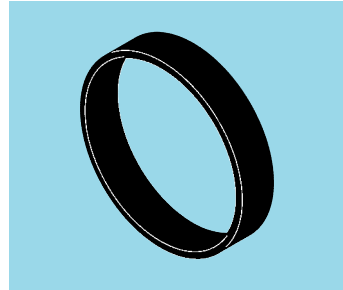

■ POLYESTER

■ HIGH SPEED

■ 6 mm WIDE

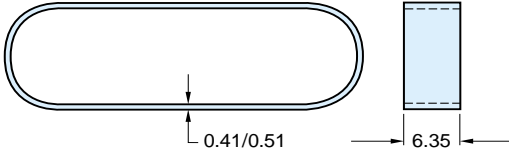

**MATERIAL:** 1 Ply Polyester Woven Cord, Black Neoprene Coating

**SPECIFICATIONS:** Maximum Belt Speed - 6100 meters/min.

Working Tension - 2.3 to 27.5 N

Length Tolerance -  $\pm 0.5\%$

Minimum Pulley Size - 6 mm Diameter

Breaking Strength - 1108 N

Catalog Number	Length	
	mm	Inch
A 6R19M13006	130	5.12
A 6R19M14006	140	5.51
A 6R19M15006	150	5.91
A 6R19M16006	160	6.30
A 6R19M17006	170	6.69
A 6R19M18006	180	7.09
A 6R19M19006	190	7.48
A 6R19M20006	200	7.87
A 6R19M22506	225	8.86
A 6R19M25006	250	9.84
A 6R19M27506	275	10.83
A 6R19M30006	300	11.81
A 6R19M32506	325	12.80
A 6R19M35006	350	13.78
A 6R19M37506	375	14.76
A 6R19M40006	400	15.75
A 6R19M42506	425	16.73
A 6R19M47506	475	18.70
A 6R19M50006	500	19.69

Special Widths - cut to size from sleeves available from stock.

### Did You Know?

...That substantial quantity discounts are available for all products?