


Super Smart Ball Bushing™ Pillow Blocks (Closed Type) for End-Supported Applications

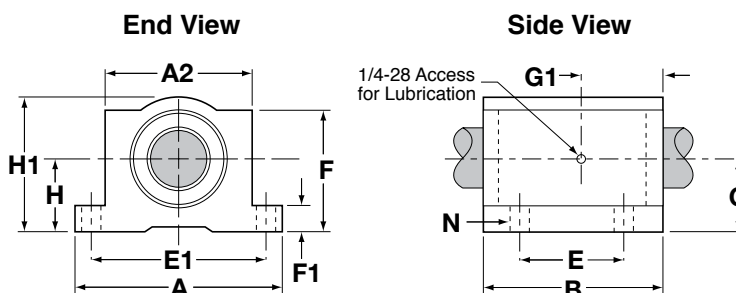

Super Smart Ball Bushing™ Pillow Blocks (Closed Type, Seal at Both Ends)
(Dimensions in inches)

Catalog Number	Nominal Diameter	A	A2	B	E ± .010	E1 ± .010	F	F1
TSS6UPB-8	.500	2.00	1.38	1.69	1.000	1.688	1.13	.25
TSSUPB-10	.625	2.50	1.75	1.94	1.125	2.125	1.44	.28
TSSUPB-12	.750	2.75	1.88	2.06	1.250	2.375	1.56	.31
TSSUPB-16	1.000	3.25	2.38	2.81	1.750	2.875	1.94	.38
TSSUPB-20	1.250	4.00	3.00	3.63	2.000	3.500	2.50	.44
TSSUPB-24	1.500	4.75	3.50	4.00	2.500	4.125	2.88	.50

Catalog Number	G	G1	H ± .003	H1	N		Pillow Block Mass lb	Dynamic* Load Capacity lbf
					Hole	Bolt		
TSS6UPB-8	.69	.72	.687	1.25	.16	#6	.23	265
TSSUPB-10	.88	.83	.875	1.63	.19	#8	.51	620
TSSUPB-12	.94	.89	.937	1.75	.19	#8	.62	1130
TSSUPB-16	1.19	1.27	1.187	2.19	.22	#10	1.24	1900
TSSUPB-20	1.50	1.68	1.500	2.81	.22	#10	2.57	2350
TSSUPB-24	1.75	1.86	1.750	3.25	.28	.25	3.94	3880

*See the chart on the bottom half of the next page.

Continued on the next page

NOTE: Catalog number is for a standard item.

For other options, add: **CR** Corrosion-Resistant, **NB** Nylon Balls, or **CM** Ceramic Balls to end of catalog number.